


MC-SA40-B

Stand-off Arm with U-bolts, 40 in

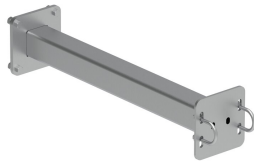

Product Classification

Product Type Universal ring mount

General Specifications

Mounting Ring mount

Dimensions

Height 254 mm | 10 in


Width 254 mm | 10 in

Length 1016 mm | 40 in

Stand-off Distance 1016 mm | 40 in

Outline Drawing

MC-SA40-B

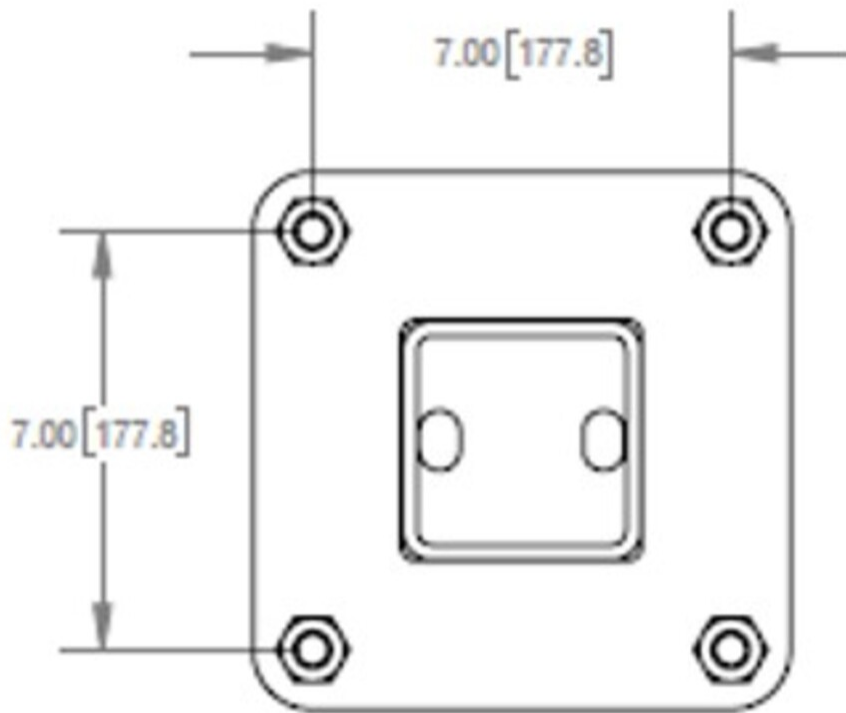

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 120 mph (BWS) at 150 ft AGL | 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC

Wind Rating Criteria Four 72 in x 8 in panel antennas per sector

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Hardware | Stand-off arms

Packaging quantity 1

Weight, net 33.1 kg | 72.973 lb

Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

MC-SA40-B

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code