


FD3-AC096J00JKBP1

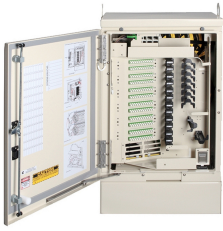

FDH 3000 Fiber Distribution Extra Small Pole Mount Cabinet, 72F, SC /APC, 0 splitters, die. LT, 96F stubs, 100 ft, 12F

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	FDH 3000

General Specifications

Access	Front
Cable Type	Dielectric - Loose Tube
Color	Putty white
Distribution Cables, quantity	1
Distribution Ports, quantity	144
Fibers per Distribution Cable, quantity	96
Fibers per Feeder Cable, quantity	12
Interface, Input	SC
Interface Feature, Input	APC
Mounting	Pole
Splitter Slots, quantity	9

Dimensions

Height	762 mm 30 in
Width	533 mm 20.984 in
Depth	356 mm 14.016 in
Cable Length	30.48 m 100 ft
Enclosure Size	Extra small

Material Specifications

Finish	Powder coated
Material Type	Steel

FD3-AC096J00JKBP1

Environmental Specifications

Environmental Space Aerial

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

