


FPCE-33YZ

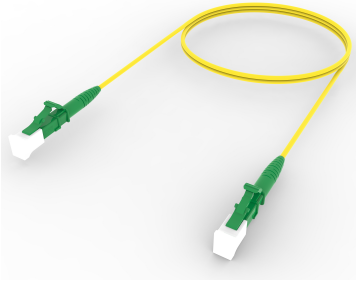

Fiber Optic Patch Cord, singlemode, 1.2 mm LSZH jacket, LC/APC-LC /APC, yellow. tuned

Product Classification

Regional Availability	Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex

General Specifications

Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Connector B, quantity	1
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	LC/APC
Interface Feature, connector A	Grade B performance
Interface, Connector B	LC/APC
Interface Feature, connector B	Grade B performance
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.2 mm 0.047 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

FPCE-33YZ

Fiber Type	G.657.A2/B2
Insertion Loss, maximum, connector A	0.25 dB
Insertion Loss, maximum, connector B	0.25 dB
Return Loss, minimum, connector A	65 dB
Return Loss, minimum, connector B	65 dB


Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Included Products

760243025	–	1.2 mm LSZH Simplex Cable
POC-FO-CAB-SX-8G-1.2MM-YL		

760243025 | POC-FO-CAB-SX-8G-1.2MM-YL

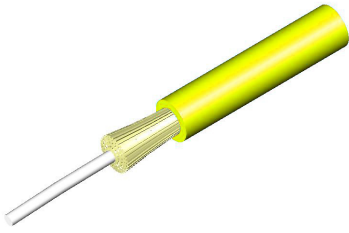

1.2 mm LSZH Simplex Cable


Product Classification

Portfolio	CommScope®
Product Type	Fiber indoor cable
Product Series	L-SP

General Specifications

Jacket Color	Yellow
Jacket Marking	Custom printing Meters
Total Fiber Count	1

Representative Image

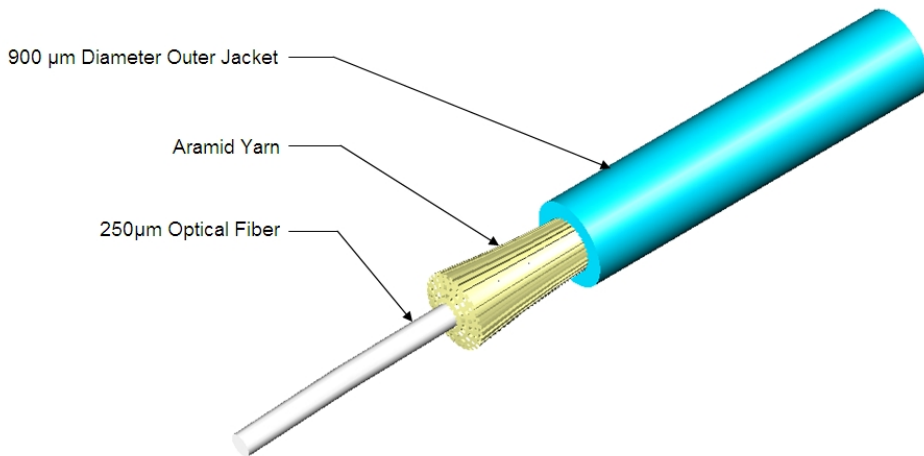

Environmental Specifications

EN50575 CPR Cable EuroClass Fire Performance	Cca
EN50575 CPR Cable EuroClass Smoke Rating	s1a
EN50575 CPR Cable EuroClass Droplets Rating	d0

EN50575 CPR Cable EuroClass Acidity Rating

a2

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

