


# FPCA-EEYZ

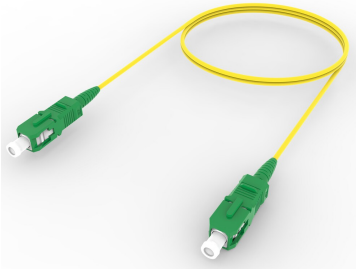

Fiber Optic Patch Cord, singlemode, 1.2 mm LSZH jacket, SC/APC-SC /APC, yellow

- 1.2 mm diameter cable provides a 65% space savings over commonly used 2.0 mm cable
- 1.2 mm diameter fiber patch cords use Reduced Bend Radius (RBR) fiber cable
- Typically used in environments where space constraints and cable routing prove most challenging

## Product Classification

<b>Regional Availability</b>	Europe   Middle East/Africa
<b>Product Type</b>	Fiber patch cord, simplex
<b>Product Series</b>	FPCA

## General Specifications


<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Green
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	1
<b>Color, boot B</b>	Green
<b>Color, connector B</b>	Green
<b>Interface, Connector A</b>	SC/APC
<b>Interface Feature, connector A</b>	Angled
<b>Interface, Connector B</b>	SC/APC
<b>Interface Feature, connector B</b>	Angled
<b>Jacket Color</b>	Yellow
<b>Total Fibers, quantity</b>	1

## Dimensions

<b>Diameter Over Jacket</b>	1.2 mm   0.047 in
-----------------------------	-------------------

## Ordering Tree

# FPCA-EEYZ

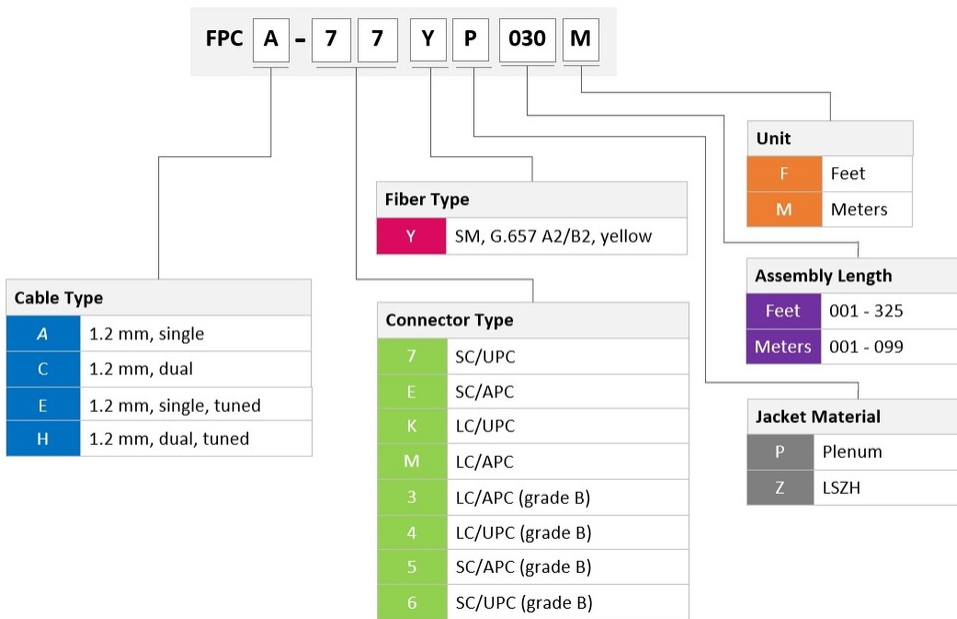

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2/B2
<b>Insertion Loss, maximum, connector A</b>	0.34 dB
<b>Insertion Loss, maximum, connector B</b>	0.34 dB
<b>Return Loss, minimum, connector A</b>	65 dB
<b>Return Loss, minimum, connector B</b>	65 dB

## Environmental Specifications

<b>Environmental Space</b>	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# FPCA-EEYZ

---


UK-ROHS

Compliant/Exempted



## Included Products

760243025                    -        1.2 mm LSZH Simplex Cable  
POC-FO-CAB-SX-8G-1.2MM-YL

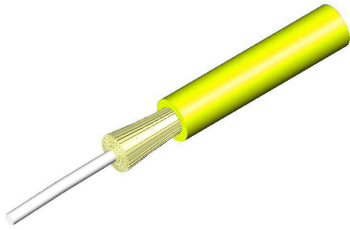

1.2 mm LSZH Simplex Cable


## Product Classification

<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber indoor cable
<b>Product Series</b>	L-SP

## General Specifications

<b>Jacket Color</b>	Yellow
<b>Jacket Marking</b>	Custom printing
<b>Total Fiber Count</b>	1

## Representative Image

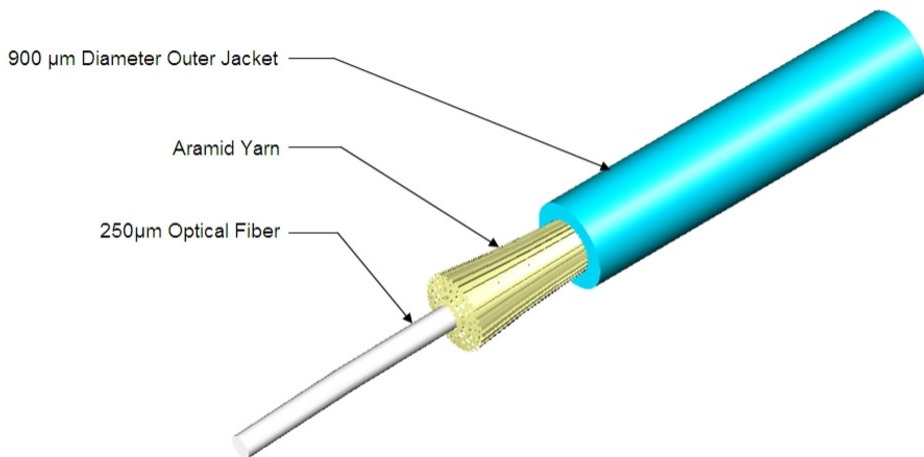

## Environmental Specifications

<b>EN50575 CPR Cable EuroClass Fire Performance</b>	Cca
---	-----

<b>EN50575 CPR Cable EuroClass Smoke Rating</b>	s1a
<b>EN50575 CPR Cable EuroClass Droplets Rating</b>	d0
<b>EN50575 CPR Cable EuroClass Acidity Rating</b>	a2

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

