


BLK-RCT-A02C0

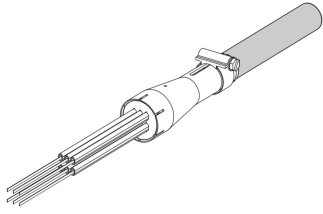

Fiber Optic Ribbon Breakout Kit, 1-12F/ribbon, 108-216F/tube, 8-11 mm central tube outside dia., 2 tubes/leg

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber breakout kit, round
Product Series	BLK-R

General Specifications

Application	For use with ribbon fiber cables
Breakout Legs, quantity	1
Fibers per Ribbon, maximum	12
Fibers per Tube, maximum	324
Tube Type	Ribbon central tube
Tubes per Leg, quantity	2

Dimensions

Tube Length	5,001.26 mm 196.9 in
Central Tube Outer Diameter	8 mm – 11 mm (0.33 in – 0.43 in)

Environmental Specifications

Environmental Space	Outdoor
----------------------------	---------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

BLK-RCT-A02C0

ROHS Compliant/Exempted

UK-ROHS Compliant

