


BLK-RIFC-A06B0

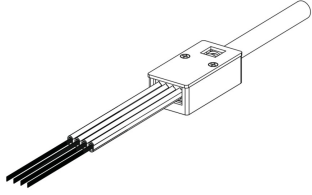

Fiber Optic Ribbon Breakout Kit, 12F/ribbon, 72F/tube, 5-8 mm central tube outside diameter, 6 tubes/leg

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber breakout kit, rectangular
Product Series	BLK-R

General Specifications

Application	For use with ribbon fiber cables
Breakout Legs, quantity	1
Fibers per Ribbon, maximum	12
Fibers per Tube, maximum	72
Tube Type	Ribbon IFC
Tubes per Leg, quantity	6

Dimensions

Tube Length	5,001.26 mm 196.9 in
Central Tube Outer Diameter	5 mm – 8 mm (0.20 in – 0.33 in)

Environmental Specifications

Environmental Space	Indoor
----------------------------	--------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

BLK-RIFC-A06B0

ROHS Compliant

UK-ROHS Compliant

