


UHVMMXMAH

Base Product

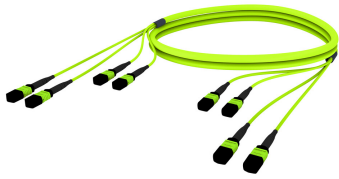

Ultra Low Loss (ULL) Multimode OM5 MPO12 (Pinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 48-Fiber, Plenum

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UHVMMXCH

Ultra Low Loss (ULL) OM5 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 48-Fiber, Armored Indoor Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East /Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTIMAX ULL

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	4
Color, boot A	Black
Color, connector A	Lime green
Connector B, quantity	4
Color, boot B	Black
Color, connector B	Lime green
Construction Type	Armored Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-12/UPC Male
Interface Feature, connector A	Pinned
Interface, Connector B	MPO-12/UPC Male


UHVMMXMXAH

Interface Feature, connector B	Pinned
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	48

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

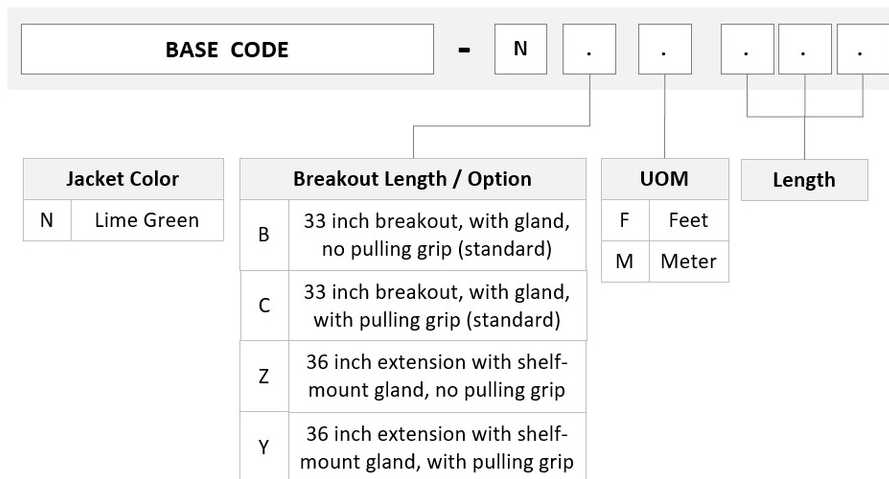

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
------------------------------	--------------------------------------

UHVMMXMAH

Environmental Space

Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- | | | |
|--------------------------------|---|---|
| 760230235
P-048-MZ-5G-F12LM | - | Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, Multimode OM5, 48 fiber multi-unit with 12 fiber subunits, Lime-green jacket color, Feet cable marking |
| 860617240 | - | MPO12, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm |