

DFT-12SM-EAS



HELIAX® Discrete trunk, DLC to UPC 12-Fiber Cable Assembly. End one 6 SM fiber armored with weather proofing shroud DLC connectors. End two 6 SM fiber with UPC connectors. CPR rated Cca s1, d1, a1.

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFT
Ordering Note	Available in Central and Latin America, Europe, Middle East, Africa, and Asia Pacific

General Specifications


Construction Type	Discrete fiber trunk
Interface, Connector A	DLC/UPC
Interface Feature, connector A	Weather shroud
Interface Body Style, connector A	Straight
Interface, Connector B	DLC/UPC
Interface Feature, connector B	Weather shroud
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	12

Dimensions

Breakout Length, connector A	999.998 mm 39.37 in
Cable Assembly Length Range (m)	0.5 – 300
Diameter Over Jacket	7 mm 0.276 in

Ordering Tree

DFT-12SM-EAS-60M

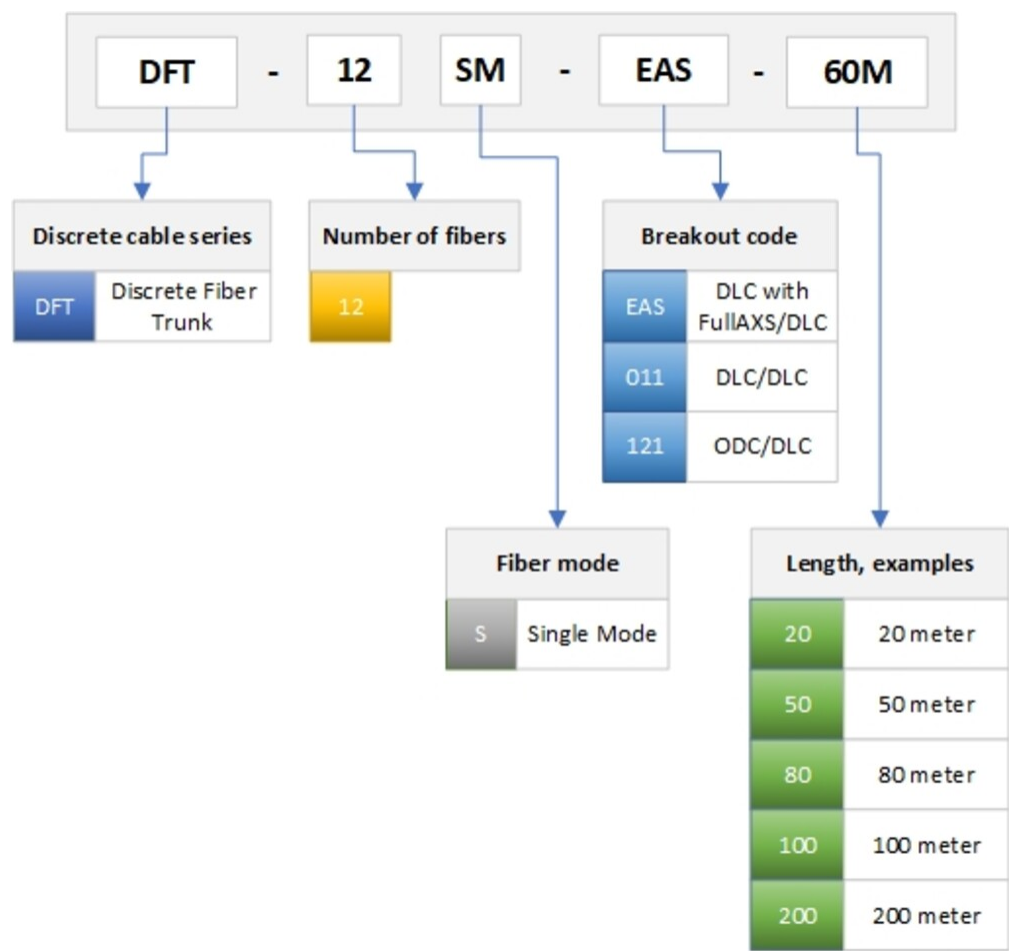

Mechanical Specifications

Minimum Bend Radius 140 mm | 5.512 in

Optical Specifications

Fiber Type G.657.A2

Environmental Specifications

Operating Temperature -40 °C to +80 °C (-40 °F to +176 °F)

EN50575 CPR Cable EuroClass Fire Performance Cca

Environmental Space Indoor/Outdoor

Qualification Standards IEC 60529:2001, IP67