


FBPS-LGX-4RU-BLK

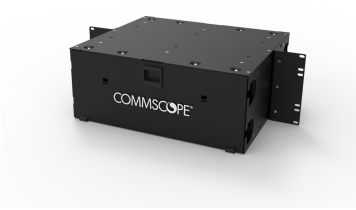

LGX 4RU chassis, 19-inch or 23-inch, back to back, maximum capacity 28 single-width LGX modules or 14 dual-width LGX modules

The LGX 4RU back-to-back chassis holds 14 single-width LGX modules per side or seven dual-width LGX modules per side

Maximum shelf density of 28 single-width LGX modules or 14 dual-width LGX modul

2.5-in., 5-in., or 8-in. recess mounting options available

Product Classification

Regional Availability	Asia Australia/New Zealand China EMEA India Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	LGX

Dimensions

Height	175.25 mm 6.9 in
Width	431.8 mm 17 in
Depth	381 mm 15 in

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing

Packaging and Weights

Packaging quantity	1
---------------------------	---