


760252370 | PPL-AP-24-LC-OM5

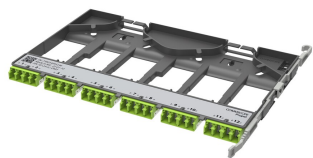

Propel pass-through adapter pack, multimode OM5, 12 duplex LC ports

- Can be installed and removed from front or rear of panel
- QR code provides easy access to product documentation
- 8f, 12f, 16f or 24f sizes are interchangeable within Propel panels or blades
- This component requires 6 of the 12 lanes on the Propel Panel blade

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber adapter pack
Product Brand	Propel
Product Series	PPL

General Specifications

Adapter Color	Lime green
Interface	LC/UPC
Interface Feature	Dust caps Internal shutters
Total Ports, quantity	12

Dimensions

Height	11 mm 0.433 in
Width	196 mm 7.717 in
Depth	170 mm 6.693 in

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Environmental Specifications

Safety Standard	c-UL-us
------------------------	---------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

