


FibrBoss Wall Mounting Fiber Optic Box, outdoor, 6 SC/UPC adapters, without pigtails

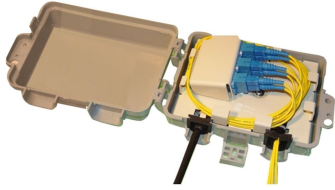

- Intended as a small patch and splice or fiber “hands-off” enclosure
- Environmentally secure housing for indoor or outdoor wall mounted application
- Accommodates field supplied flat or round drop cable inputs
- Cable retention brackets are integrated into the fiber management tray
- Splice protection sleeves are included to add customer convenience and efficiency

Product Classification

Regional Availability	Asia Australia/New Zealand Latin America North America
Product Type	Fiber wall box
Product Series	PB06

General Specifications

Functionality	Patching Splicing
Access	Front
Application	For cables with outer diameter up to 10 mm: each on both sides
Enclosure Color	Beige
Front Cover Type	Hinged with lock
Interface	SC/UPC
Lock Type	Padlock ready
Mounting	Pedestal Pole Wall
Port, quantity	6
Splicing Capacity, maximum	6

Dimensions

Height	121.92 mm 4.8 in
Width	162.56 mm 6.4 in
Depth	60.96 mm 2.4 in

Material Specifications

Enclosure Material Type	LSZH thermoplastic
--------------------------------	--------------------

Optical Specifications

R35712-000 | F-PB06-BC2-RNN-S1N00-05

Fiber Mode	Singlemode
Insertion Loss, Terminal Connector, maximum	0.2 dB
Return Loss, Connector, minimum	55 dB

Environmental Specifications

Environmental Space	Outdoor
Flammability Rating	UL 94 V-0
Qualification Standards	IEC 60529, IP65

Packaging and Weights

Included	Splice protectors Splice tray
Packaging quantity	1
Packaging Type	Box Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

