


# U3XQPQXTK

## Base Product

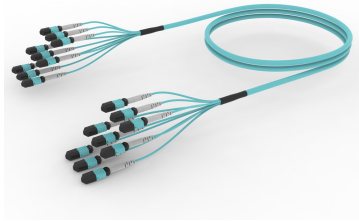

Ultra Low Loss (ULL) OM4 MPO8 (Non-Pinned) to MPO8 (Pinned), Fiber Trunk Cable Assembly, 72-Fiber, LZSH B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	9
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Aqua
<b>Connector B, quantity</b>	9
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/UPC Female
<b>Interface, Connector B</b>	MPO-08/UPC Male
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	72

## Dimensions

<b>Breakout Length</b>	22 in
------------------------	-------



# U3XQPQXTK

---

## Included Products

- 760253122  
N-072-MP-5K-F08AQ/20T/B2 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber multi-unit with 8 fiber 2.0mm subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860659018 – MPO-08, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 2mm
- 860659024 – MPO-08, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 2mm