

UGVQPUCT8

Base Product



Ultra Low Loss (ULL) OM5 MPO8 (Non-Pinned) to unconnectorized, Fiber Trunk Cable Assembly, 8-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Lime green
Connector B, quantity	0
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	Unterminated
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

Dimensions


Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

UGVQPUCT8

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

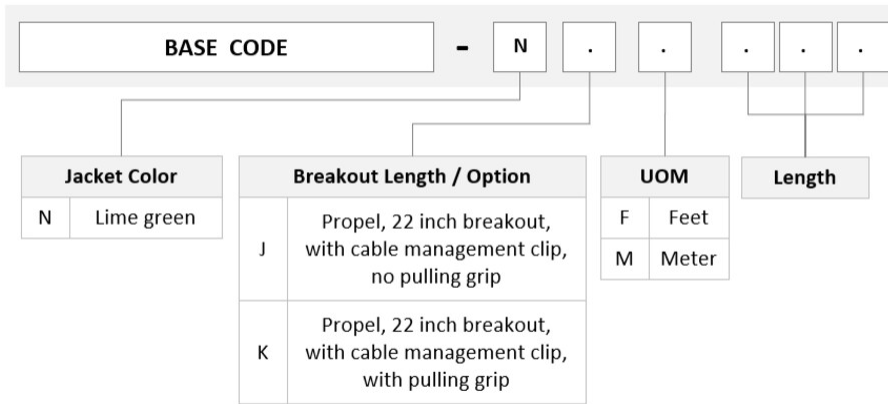

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Indoor | Plenum

Regulatory Compliance/Certifications

Agency

Classification

ANATEL

Compliant

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system



Included Products

760248188

- Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 8 fiber, Multimode OM5, Feet jacket

Page 2 of 3

UGVQPUCT8

P-008-MP-5G-F08LM/20T
860659026

– marking, Aqua jacket color
MPO-08, ULTRA LOW LOSS, FEMALE, OM5, LIME-GREEN, 2mm