


UQX2P2EBH

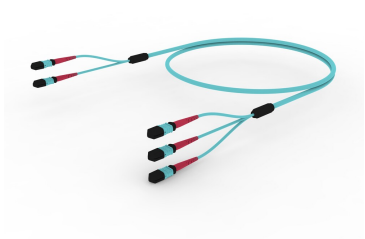

Ultra Low Loss (ULL) OM4 , 2X3, MPO24 (Non-Pinned) to MPO24 (Non-Pinned-QSFP), 48-Fiber, Conversion Array, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	2
Color, boot A	Red
Color, connector A	Aqua
Connector B, quantity	3
Color, boot B	Red
Color, connector B	Aqua
Construction Type	Stranded
Fibers per Subunit, quantity	24
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Female
Interface, Connector B	MPO-24/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	48

Dimensions

UQX2P2EBH

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

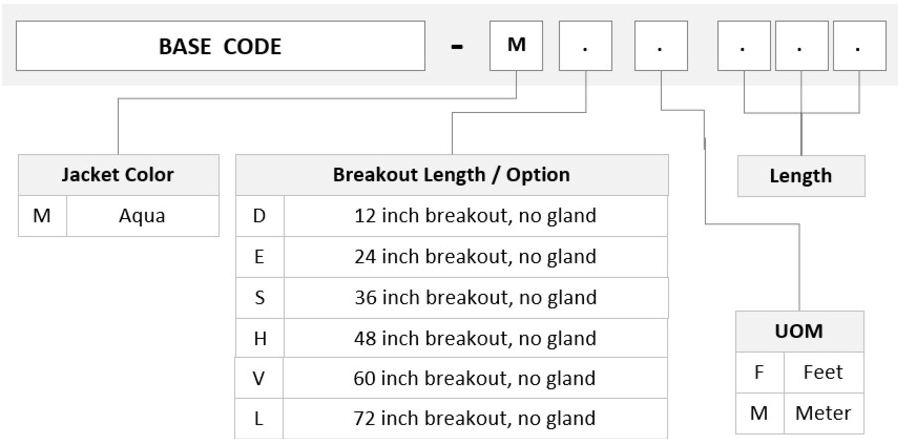

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
-----------------------------------	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

UQX2P2EBH



Included Products

300100114770	-	MPO24,FEMALE,OM3/4,AQUA,3.6mm
760161927	-	Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 48 fiber with 24 fiber subunits,
P-048-MP-5K-F24AQ		Multimode OM4, Feet jacket marking, Aqua jacket color
860662277	-	MPO24,FEMALE,OM3/4,AQUA,3.0MM