


URG2DMXAH

Base Product

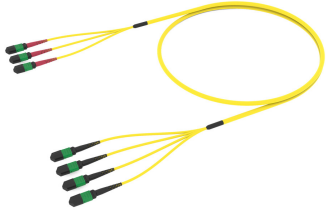

Ultra Low Loss (ULL) Singlemode G.657.A2, 3X4, MPO24 (Non-Pinned - QSFP-DD) to MPO12 (Pinned), 48-Fiber, Conversion Array, LSZH

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	3
Color, boot A	Red
Color, connector A	Green
Connector B, quantity	4
Color, boot B	Black
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-24/APC Female
Interface, Connector B	MPO-12/APC Male
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	48

Dimensions

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
------------------------	---

URG2DMXAH



Included Products

760237975
N-048-MP-8G1-F12YL/D

- Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating

860638317

- MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm

860662281

- MPO24,FEMALE,SM, GREEN,3.0MM