


# D137HLSG

---

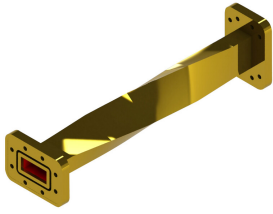

90° Rigid Twist for WR137, 5.85–8.2 GHz, with interface types UDR70 and PDR70, 12 in, gray

## Product Classification

**Product Type** Rectangular waveguide, rigid twist

## General Specifications

**Component** 90° Rigid Twist

**Interface** UDR70

**Interface 2** PDR70

## Dimensions

**Length** 305 mm | 12.008 in

**Waveguide Size** WR137 | WG14 | R70

## Electrical Specifications

**Operating Frequency Band** 5.85 – 8.2 GHz

**VSWR** 1.06

## Material Specifications

**Finish** Gray

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

