


VZWSMART-MSK4 | LEVELING PIPE KIT

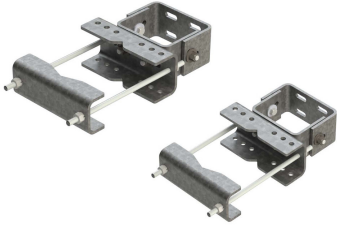

LEVELING PIPE KIT

Pipe Mount Leveling Kit, attaches up to 8" OD or 60 degree angle or up to 6" 90 degree angle Tower Legs, For Pipes 2-3/8" to 4-1/2" OD, U-Bolts sold separately

Product Classification

Product Type	Clamp set
Ordering Note	CommScope® non-standard product

General Specifications

Mounting	Round and angle legs
-----------------	----------------------

Dimensions

Mounting Diameter 2, maximum	203.2 mm 8 in
Mounting Diameter, maximum	114.3 mm 4.5 in
Mounting Diameter, minimum	60.325 mm 2.375 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Packaging and Weights

Included	Brackets Clamp halves Threaded rod
Packaging quantity	2

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant

