

PGP-CS16



Polymer PIM-Guard Antenna and RRU Cable Support Bracket with 16 positions / 32 cables for stackable hangers (up to 2 per position)

Compatible with first and second generation Polymer PIM-Guard products

-SSH-1416

-SSH-411

-SSH-1117

Product Classification

Product Type Support bracket

Product Brand PIM-Guard

General Specifications

Cable Runs, quantity 16

Hole, quantity 16

Mounting Round member

Dimensions

Height 50.8 mm | 2 in

Width 304.8 mm | 12 in

Length 431.8 mm | 17 in


Mounting Diameter, maximum 76.2 mm | 3 in

Mounting Diameter, minimum 60.96 mm | 2.4 in

Hole Size 3/4 in

Ordering Tree

PGP-CS16

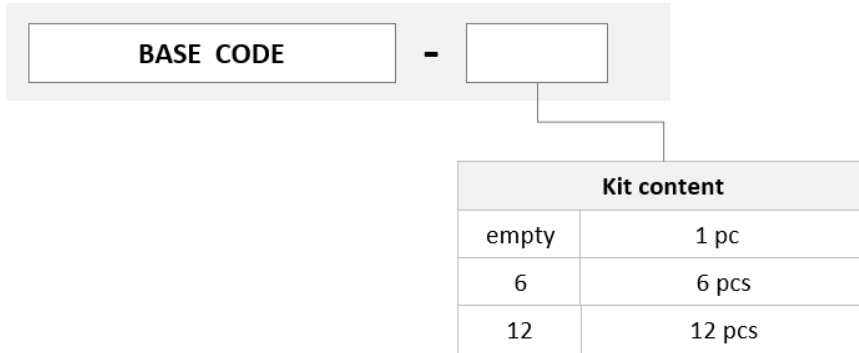

Material Specifications

Material Type Polymer

Packaging and Weights

Packaging quantity 1

Weight, net 1.16 kg | 2.557 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

