


# A-VF1-EOXXG

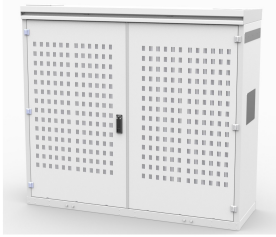

## Cheshire Cabinet with rails and brackets fitted to accommodate up to 12 Ericsson Radios

- Includes fans with controller
- Supplied with 20 meter fan controller power cable
- Supplied with 20 meter alarm cable
- Contains two GPS windows ( blanked and plastic covered)

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Outdoor cabinet

## General Specifications


<b>Access</b>	Double door
<b>Accessories</b>	Cable plate   External alarm connection   Hangers   In-ground root   Plinth
<b>Cabinet Type</b>	Combiner cabinet   Radio cabinet
<b>Cable Entry Location</b>	Bottom
<b>Color</b>	Green (RAL 6009)   Light Gray (RAL 7035)   Others available at additional cost
<b>Cooling</b>	175 mm fan (2)
<b>Door Security</b>	Internal door contact   Swing handle with European profile cylinder
<b>Door Type, front</b>	Key lock (included)   Non-removable
<b>Door, quantity</b>	2
<b>Front Door Type</b>	Single hinged
<b>Lock Type</b>	Key lock
<b>Mounting</b>	In-ground root   Plinth
<b>Radios Included</b>	None

## Dimensions

<b>Height</b>	1,721.866 mm   67.79 in
<b>Width</b>	1,899.92 mm   74.8 in
<b>Depth</b>	599.948 mm   23.62 in

## Dimension Drawing

# A-VF1-EOXXG

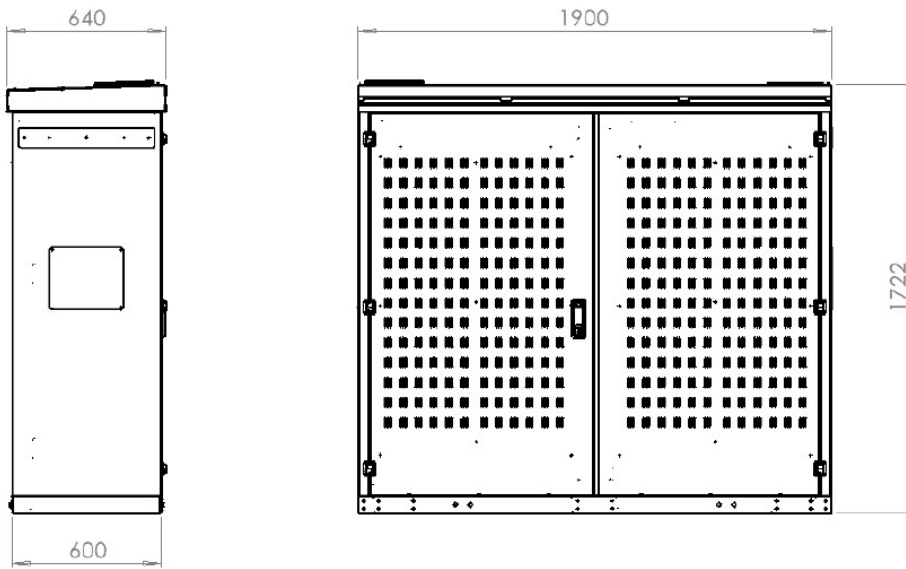

## Material Specifications

<b>Finish</b>	Powder coated
<b>Material Type</b>	Galvanized steel

## Environmental Specifications

<b>Qualification Standards</b>	IP33
--------------------------------	------

## Packaging and Weights

<b>Weight, net</b>	299.997 kg   661.38 lb
--------------------	------------------------

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

