


U4VQXLUTM

Base Product

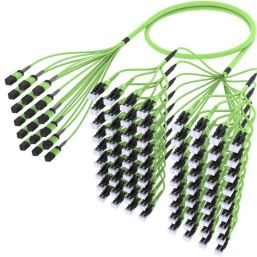

Ultra Low Loss ULL OM5 MPO8 UPC pinned to LC/UPC Uniboot Ruggedized fanout Cable, 144-Fiber, LSZH, 8 fiber PmP 2.0 mm /B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	18
Color, boot A	Gray
Color, connector A	Lime green
Connector B, quantity	144
Color, boot B	Lime green
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	144

Dimensions

U4VQXLUTM

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|---------------------------------------|---|---|
| 760253114
N-144-MP-5G-F08LM/20T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber with 2.0 mm Subunits, Multimode OM5, Gel-free, Meters jacket marking, Lime green jacket color, B2ca Flame rating |
| 860658162 | - | 2.0 mm LC Uniboot GEN 1.5, Lime Green |
| 860659021 | - | MPO8, LL, MALE, OM5, LIME, 2MM |