


# UKGMXXMXCL

## Base Product

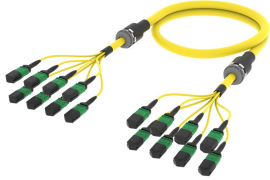

Singlemode MPO12 APC (pinned) to MPO12 APC (pinned) Fiber Trunk Cable Assembly, 96-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Connector A, quantity

8

### Color, boot A

Black

### Color, connector A

Green

### Connector B, quantity

8

### Color, boot B

Black

### Color, connector B

Green

### Construction Type

Armored | Stranded

### Furcation Color

Yellow

### Interface, Connector A

MPO-12/APC Male

### Interface, Connector B

MPO-12/APC Male

### Jacket Color

Yellow

### Polarity

Method B Enhanced (ULL)

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

96

## Dimensions

### Breakout Length

22 in

# UKGMXXMCL

<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree



## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>EN50575 CPR Cable EuroClass Fire Performance</b>	Dca
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# UKGMXXMCL

---

UK-ROHS

Compliant/Exempted



## Included Products

- 760256105  
N-096-MZ-8G1-F12YL/20T/B2 - Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 96 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860659010 - MPO-12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm