


# MTC3914M3

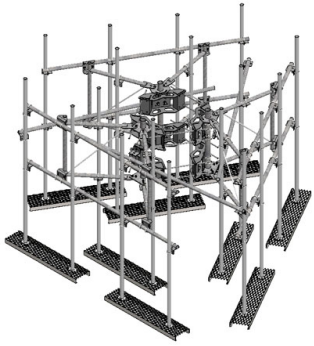

G22 High Capacity 3-Sector Monopole Frame with Work Platform, 10 ft 6 in face, includes twelve 126 in pipes; For patents, see [www.cs-pat.com](http://www.cs-pat.com).

## OBSOLETE

This product was discontinued on: July 29, 2022

## Product Classification

**Product Type** High capacity monopole sector frame

## General Specifications

**Mounting** Monopole, 304.8–1270 mm (12–50 in) OD  
**Pipe, quantity** 12  
**Sectors, quantity** 3

## Dimensions

**Height** 3,200.4 mm | 126 in  
**Face Width** 3.2 m | 10.5 ft  
**Width** 3,200.4 mm | 126 in  
**Pipe Length** 3,200.4 mm | 126 in  
**Face Support Pipe Diameter** 60.325 mm | 2.375 in  
**Mounting Diameter, maximum** 1270 mm | 50 in  
**Mounting Diameter, minimum** 304.8 mm | 12 in  
**Pipe Outer Diameter** 60.325 mm | 2.375 in  
**Stand-off Distance** 1,117.6 mm | 44 in  
**Mounting Circumference, maximum** 1270 mm | 50 in  
**Mounting Circumference, minimum** 304.8 mm | 12 in

## Material Specifications

# MTC3914M3

---

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** For Specifications, please contact [steelproducts@commscope.com](mailto:steelproducts@commscope.com) or call 800-255-1479

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Pipe mounts | Plain end pipes (12) | Platform | Ring mounts (2) | Sector frames (3) | Stiff arm

**Packaging quantity** 1

**Weight, net** 1,225.607 kg | 2702 lb

## Regulatory Compliance/Certifications

### Agency

ISO 9001:2015



### Classification

Designed, manufactured and/or distributed under this quality management system

## \* Footnotes

**Wind Rating** BWS—Base Wind Speed; FBC—Florida Building Code