


MTC3984

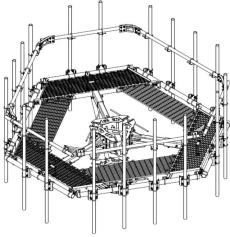

6-Sector Monopole Platform kit, 12 in to 50 in OD, (3) 8 ft faces, (3) 6 ft faces, includes (18) 96 in antenna pipes

Product Classification

Product Type	Co-location platform
Ordering Note	NSTD445 Compliant

General Specifications

Mounting	Monopole, 304.8–1270 mm (12–50 in) OD
Pipe, quantity	18
Sectors, quantity	6

Dimensions

Height	2667 mm 105 in
Width	1,828.8 mm 72 in 2,438.4 mm 96 in
Length	1,950.72 mm 76.8 in
Pipe Length	2,438.4 mm 96 in
Mounting Diameter, maximum	1270 mm 50 in
Mounting Diameter, minimum	304.8 mm 12 in
Pipe Outer Diameter	60.96 mm 2.4 in
Stand-off Distance	1,950.72 mm 76.8 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating	For Specifications, please contact steelproducts@commscope.com or call 800-255-1479
Wind Rating Test Method	TIA/EIA-222

Packaging and Weights

Included	Pipe mounts Plain end pipes Platform Rail Ring mounts (2)
-----------------	---

MTC3984

Packaging quantity 1
Weight, net 1,303.624 kg | 2874 lb

* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code