


# UKXRZRZ8N

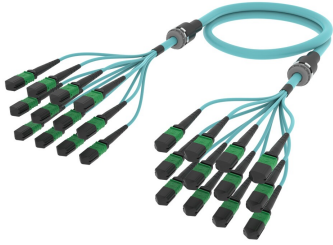

Ultra Low Loss (ULL) OM4 MPO16 APC (pinned) to MPO16 APC (pinned), Fiber Trunk Cable Assembly, 192-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	12
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	12
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-16/APC Male
<b>Interface, Connector B</b>	MPO-16/APC Male
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	16
<b>Total Fibers, quantity</b>	192

## Dimensions


<b>Breakout Length</b>	22 in
------------------------	-------

# UKXRZRZ8N

**Cable Assembly Length Range (m)** 3 – 305

**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

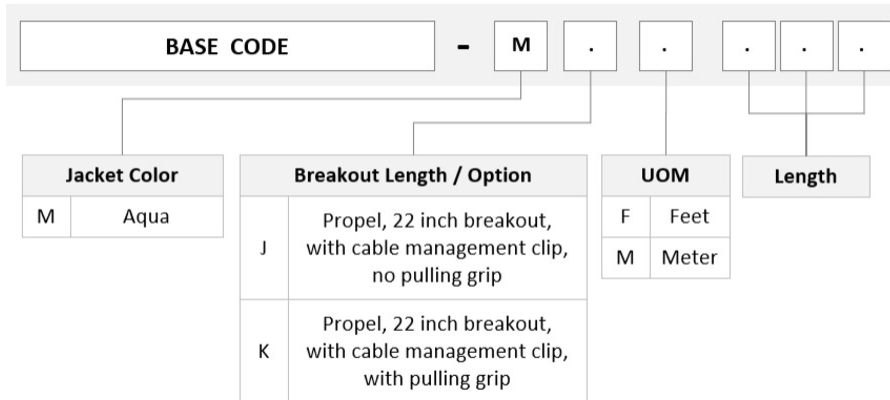

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance** Dca

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# UKXRZRZ8N

---



## Included Products

- 760256200  
N-192-MZ-5K-F16AQ/30T/B2 – Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, OM4 multimode, 192 fiber, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860659158 – Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, pinned, green, for 3 mm cable