


# SF-HPM35-B

---

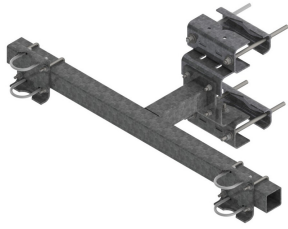

Heavy Duty Square T-Arm Base Kit for 3-1/2 in OD face pipe supports, pipe ordered separately

## Product Classification

**Product Type** Co-location dual pipe mount kit

## General Specifications

**Mounting** Angle 60°, 203.2 mm (8 in) | Angle 90°, 152.4 mm (6 in) | Straight or tapered legs up to 203.2 mm (8 in) OD

**Pipe, quantity** 0

**Tower Taper** Non-tapered | Tapered

## Dimensions

**Height** 355.6 mm | 14 in

**Face Width** 1.676 m | 5.5 ft

**Width** 1,676.4 mm | 66 in

**Length** 609.6 mm | 24 in

**Mounting Diameter, maximum** 203.2 mm | 8 in

**Mounting Diameter, minimum** 0 mm | 0 in

**Pipe Outer Diameter** 88.9 mm | 3.5 in

**Stand-off Distance** 508 mm | 20 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** 120 mph (BWS) at 100 ft AGL

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Clamps | Frame | Pipe mounts | Saddle mounts

# SF-HPM35-B

---

**Packaging quantity** 1  
**Weight, net** 83.506 kg | 184.1 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

**Wind Rating** BWS—Base Wind Speed; FBC—Florida Building Code