


2105086-2

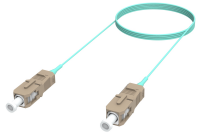

Fiber Optic Patch Cord, Simplex, 0.9mm, LSZH, Multimode OM4, SC/UPC to SC/UPC, Aqua, 2 m

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Series	210

General Specifications


Connector A, quantity	1
Color, boot A	Aqua
Color, connector A	Beige
Connector B, quantity	1
Color, boot B	Aqua
Color, connector B	Beige
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Total Fibers, quantity	1

Dimensions

Cord Length	2 m 6.562 ft
Diameter Over Jacket	0.9 mm 0.035 in

Ordering Tree

 2105086-2



Examples of Lengths (meters)	
-1	1 meters
-2	2 meters
-3	3 meters
1- -0	10 meters

Mechanical Specifications

Cable Retention Strength, maximum 1.00 lb @ 0 ° | 1.00 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®
Insertion Loss, maximum 0.3 dB
Return Loss, minimum 27 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted

