


FGS-MHRT-M/H

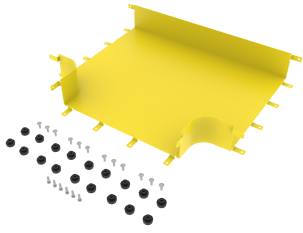

FiberGuide® Horizontal T, 4x18in, 4x24in Exit, Yellow

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Tee |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|------------------------|-------------|
| Product Feature | Transition |
| Color | Yellow |
| Orientation | Horizontal |
| Section Type | Tee section |

Dimensions

| | |
|--------------------------|---|
| Height | 114 mm 4.488 in |
| Width | 476 mm 18.74 in |
| Length | 905 mm 35.63 in |
| System Dimensions | 102 mm x 457 mm (4 in x 18 in) 102 mm x 610 mm (4 in x 24 in) |

Ordering Tree

FGS-MHRT-M/H

9 10
 FGS B - MHRT - H

Section Color

| | | |
|---|-------|--------|
| 9 | empty | yellow |
| | B | black |

Section Size

| | | |
|-----|-----------|---|
| 10 | A | 4 x 4 in |
| | B | 4 x 6 in |
| | B-VS | 4 x 6 in, variable support bracket |
| | F | 4 x 12 in |
| | F/B | 4 x 12 in, 6 in exit |
| | F/B-S | 4 x 12 in, 6 in exit, with variable support bracket |
| | F/B-VS | 4 x 12 in, 6 in exit, variable support bracket |
| | F-VS | 4 x 12 in, variable support bracket |
| | G | 2 x 6 in |
| | H | 4 x 24 in |
| | H/F | 4 x 24 in, 12 in exit |
| | H/F-VS | 4 x 24 in, 12 in exit, variable support bracket |
| | M | 4 x 18 in |
| | M/F | 4 x 18 in, 12 in exit |
| | M/H | 4 x 18 in, 24 in exit |
| H/M | 4 x 18 in | |

* Support brackets only come in black

Material Specifications

Material Type Steel

Environmental Specifications

Safety Standard CSA | UL

Packaging and Weights

Weight, net 2.95 kg | 6.504 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant

