


URXQZBVF8

Base Product

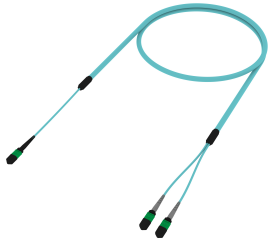

Ultra Low Loss (ULL) OM4, 1X2, MPO8 Multimode APC (Pinned) to MPO4 Multimode APC (Non-Pinned), 8-Fiber, Conversion Array, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	2
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-04/APC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8


Dimensions

URXQZBVF8

Cable Assembly Length Range (m) 1 – 305

Cable Assembly Length Range (ft) 3 – 999

Ordering Tree

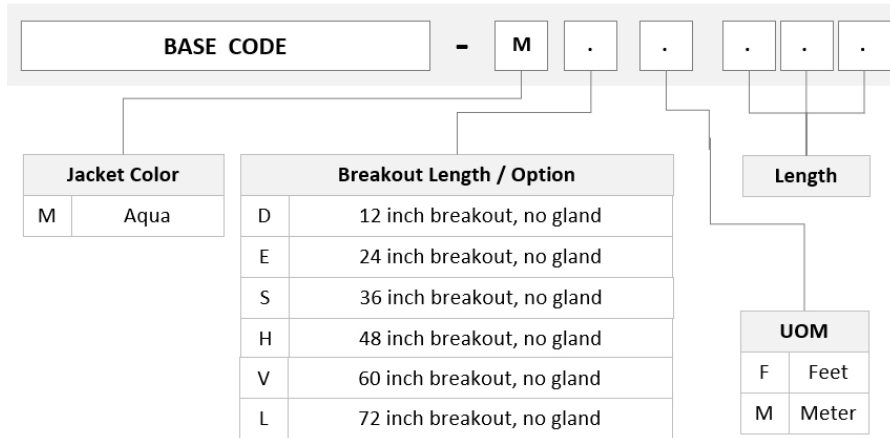

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Included Products

- 760251447 N-008-MP-5K-F20AQ/E – LazrSPEED® Low Smoke Zero Halogen Riser Light Duty Interconnect Cable, 8 fiber
- 860662230 – MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm
- 860662232 – MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm