


TES-SS-MSK12 | UNIVERSAL CROSSOVER PLATE

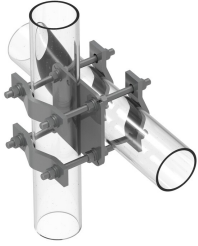

Universal Crossover Plate, connects up to 4-1/2" OD x 4-1/2" OD Pipe (Pipe not included)

Product Classification

Product Type Clamp plate

General Specifications

Mounting Crossover plate

Dimensions

Mounting Diameter 2, maximum 114.3 mm | 4.5 in

Mounting Diameter 2, minimum 42.164 mm | 1.66 in

Mounting Diameter, maximum 114.3 mm | 4.5 in

Mounting Diameter, minimum 42.164 mm | 1.66 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Clamps | Hardware | Plates

Packaging quantity 1

Weight, net 10 kg | 22.046 lb