


TES-SS-MSK13 | UNIVERSAL CHANNEL  
CROSSOVER

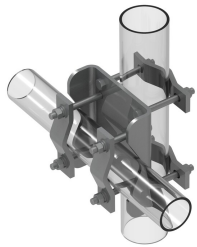

Universal Channel Crossover Plate, connects up to 4-1/2" OD x 3-1/2" OD Pipe  
(Pipe not included)

## Product Classification

<b>Product Type</b>	Clamp plate
---------------------	-------------

## General Specifications

**Mounting** Crossover plate

## Dimensions

<b>Mounting Diameter 2, maximum</b>	88.9 mm   3.5 in
-------------------------------------	------------------

**Mounting Diameter 2, minimum** 42.164 mm | 1.66 in

<b>Mounting Diameter, maximum</b>	114.3 mm   4.5 in
-----------------------------------	-------------------

**Mounting Diameter, minimum** 42.164 mm | 1.66 in

## Material Specifications

<b>Material Type</b>	Hot dip galvanized steel
----------------------	--------------------------

## Packaging and Weights

**Included**                      Clamps | Hardware | Plates

<b>Packaging quantity</b>	1
---------------------------	---

**Weight, net** 11.7 kg | 25.794 lb