


TES-SS-SFK1 | TIE BACK ASSEMBLY

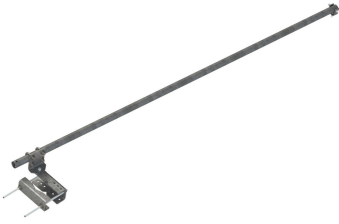

Tieback Bracket / Stiff Arm, 2-3/8" OD x 12 ft Pipe with Attachment Hardware, for 1-1/2" to 8" OD or 60 degree angle tower leg

Product Classification

Product Type Stiff arm mount

General Specifications

Mounting Round and angle legs

Pipe, quantity 1

Dimensions

Pipe Length 3,048 mm | 120 in

Pipe Outer Diameter 60.325 mm | 2.375 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment hardware | Pipe

Packaging quantity 1

Included Products

SA-B – Stiff Arm /Tieback Brackets for 2-3/8 in OD pipe - Pipe not included



Stiff Arm /Tieback Brackets for 2-3/8 in OD pipe - Pipe not included

Product Classification

Product Type Stiff arm mount

General Specifications

Mounting Round and angle legs

Pipe, quantity 0

Dimensions

Height 152.4 mm | 6 in

Width 203.2 mm | 8 in

Length 203.2 mm | 8 in

Mounting Diameter, maximum 88.9 mm | 3.5 in

Mounting Diameter, minimum 48.26 mm | 1.9 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment hardware | Brackets

Packaging quantity 1

Weight, net 8.301 kg | 18.3 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

SA-B

ROHS

Compliant

UK-ROHS

Compliant

