

UJGQXQXRY

Base Product

Ultra Low Loss Singlemode MPO8 Pinned to MPO8 Pinned 1728-Fiber Pre-terminated Trunk Cable, Low Smoke Zero Halogen/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Gray
Color, connector A	Green
Color, boot B	Gray
Color, connector B	Green
Construction Type	Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Male
Interface Feature, connector A	Angled
Interface, Connector B	MPO-08/APC Male
Interface Feature, connector B	Angled
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	1728

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

UJGQXQRY

Ordering Tree

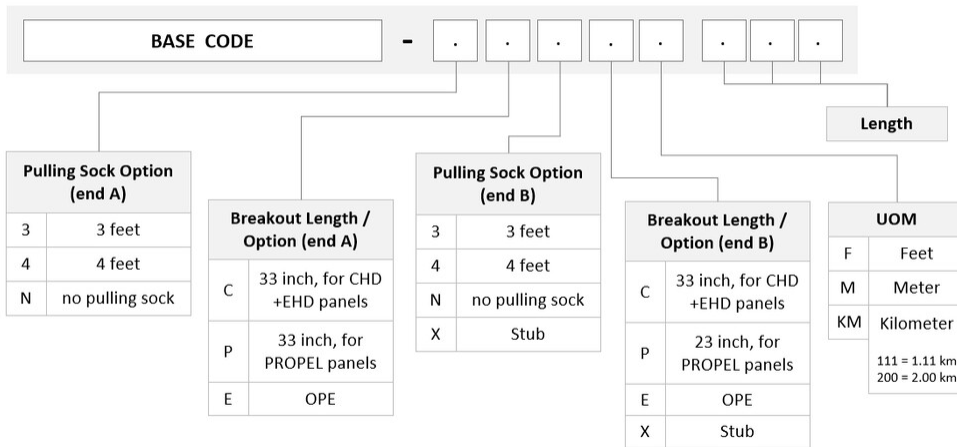

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

- 760244182 - Fiber indoor cable, All-Dielectric, LSZH Riser-Rated, Gel-Free, Loose Tube Rollable Ribbon, 1728 fiber, Singlemode G.657.A2, Feet jacket marking, Yellow jacket color
- N-1728-LN-RR-F12YL/8G/99H/C
- 860637705 - MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm