



OFDC C12 Fiber Optic Series with Rural Taps, Gel Cable sealing, 4 drop taps @ 7dB each with terminating tap, No mounting kit

- Advanced gel sealing technology ensures fast and easy field handling without a need for special tools
- Individual access to drop cable connection area and separate zones for looped cable storage for most cable types
- Compact and modular design suited for wraparound drop cable installation, enabling faster deployments
- Allows easy pass-through cabling and integration of optical components, even at later deployment stages

Product Classification

Regional Availability	Asia EMEA Latin America North America
Product Type	Single-ended, rectangular fiber closure
Product Series	OFDC
Government Funding	Build America Buy America (BABA) compliant*

General Specifications

Cable Capacity, Drop	12 Flat 8.0 x 4.5 mm (0.30 x 0.17 in) 12 Round 1.5–5.5 mm (0.06–0.21 in) 24 Round 2.0–5.5 mm (0.07–0.21 in)
Cable Capacity, Feeder	2 Round 5.5–17.5 mm (0.21–0.68 in)
Cable Ports Quantity, total	4 round ports + 12 multi-out ports (24 cables)
Cable Sealing Type	Compressed gel
Closure Sealing Type	Hinged with latch
Closure Style	Single-ended
Color	Black
Mounting	Manhole Pedestal Strand Wall
Port Type	SC/APC
Port, quantity	12
Splice Tray Included, quantity	2
Splice Tray Type Included	48-way, heat shrink
Splicing Capacity, maximum	96
Splicing Type, Supported	Single fusion
Splitter Type	No splitter


760258557-US | OFDC-C12-S2/40-4T07T-N-HD-US

Splitter, quantity 0

Dimensions

Height 118 mm | 4.646 in
Width 214 mm | 8.425 in
Length 370 mm | 14.567 in
Splice Protector Length, maximum 45 mm | 1.772 in

Ordering Tree

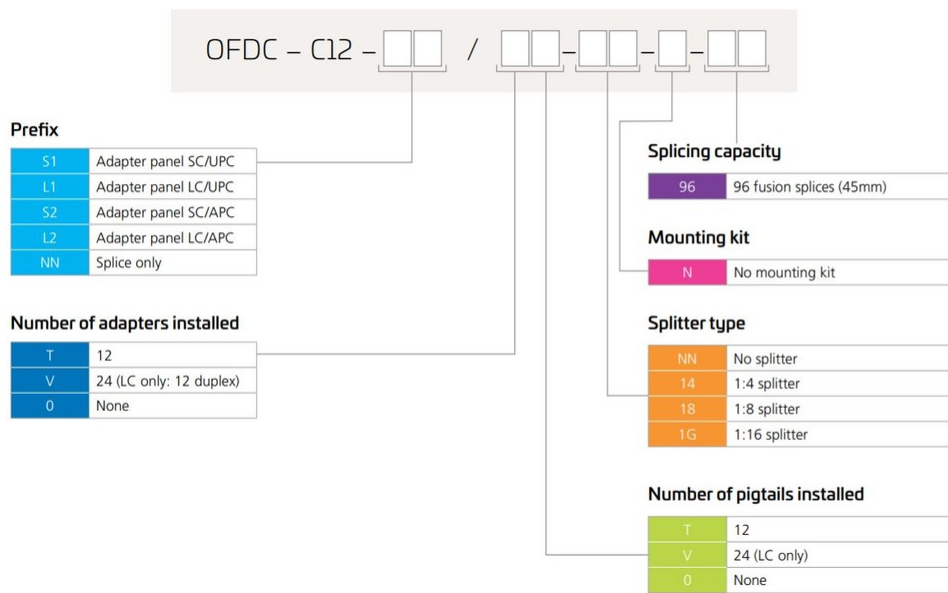

Material Specifications

Material Type Rugged polymer

Environmental Specifications

Installation temperature -5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity 93%, non-condensing
Environmental Space Above ground | Below ground
Qualification Standards IEC 60529, IP68 + 2 m waterhead
UV Resistance UV stabilized

Packaging and Weights

Included	Fiber pigtail assemblies (12) SC/APC adapters (12)
Packaging quantity	1
Packaging Type	Box Carton
Weight, net	2.5 kg 5.512 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

